

Linear Fluorescent Lampholders



- Miniature Bi-Pin
 - Low and tall profile, snap-in/slide-on for T-5, shunted and non-shunted
 - T-8 to T-5 adapter
 - Butt-on for T-5
- Medium Bi-Pin
 - Internal shunt for use with electronic ballasts
 - Slide-on and snap-in/slide-on for T-8 and T-12, shunted and non-shunted
 - Low and tall profile turn-type for T-8 and T-12, shunted and non-shunted
 - Low profile, straight-in for T-8 and T-12, shunted and non-shunted
 - Straight-in, butt-on or self-locking
 - Slide-on for T-8 and T-12, U-shape lamps
 - Disconnect (circuit-interrupting) bi-pin, low and tall profile
 - Butt-on, automatic locking and ejection
- Snap-in Quickwire for slimline, medium bi-pin and high output
- Pedestal type for medium bi-pin, high output and recessed double contact
- Connectors and starter bases

Compact Fluorescent Lampholders (CFL's)



- Styles with G24q/GX24q base, G24d base, GX23/GX23-2 base and G23/G23-2 base
- Expanded line includes high-wattage (57W and 70W) devices and round-shape styles
- Long twin-tube with 2G11 base
- Lamp support clips in plastic and stainless steel for 2G11

Lampholders for Innovative Light Sources



- Multi-base miniature bi-pin quartz
- High-heat ceramic or LCP resin body for T-5 and T-3 1/4 wedge-base
- High-heat ceramic for G4 bi-pin base
- Metal halide lampholders for a variety of lamp bases, including G8.5 (with lead-in edge), GX8.5 and GU10
- Intellicircuit® transformer-less series circuit board for low-voltage lamps
- Wedge-base for T-5 and T-3 1/4 miniature incandescent lamps
- Tungsten-halogen double-ended metal halide and high pressure sodium with R7s/RX7s caps
- Double-contact bayonet with BA15d base
- Metal halide/high pressure sodium lamps with G12 or PG12 base

Mogul/Medium HID Lampholders



- 6KV pulse-rated for a wide range of mogul lamps
- E40/45 base European mogul
- Open-fixture moguls: Rated 1500W-600V, 4KV pulse-rated
- Position-oriented moguls with quick-connect tabs or leads
- Pulse-rated medium base for HID and incandescent applications
- Low-pressure sodium single-end bayonet base
- Par connectors for mogul base and medium base
- Open fixture medium base HID sockets: Rated 660W-600V, 4KV pulse-rated

Incandescent Lampholders and Brackets



- Keyless Fixture lampholders
 - Medium base phenolic and porcelain
 - Style AP
 - Twin, one-piece, two-piece and front-mounted versions
 - Ring type or side outlet
- Wide assortment of mounting brackets
- Snap in styles, phenolic or porcelain with double spring clips or angle mounted
- Candle sockets with bottom turn knob, medium base
- Multi lampholder clusters, two-light and three-light versions
- Pony cleat receptacles
- Adapters and extensions
- Pin type lampholders, medium and candelabra base

Thermal Protectors



- Self-Heating Thermal Protectors (SHTP's) for recessed incandescent, fluorescent and HID lighting
- Custom designed in-line wiring harness sets

Metal Shell Lampholders



- Medium base in turn knob, push-thru, pull-chain, key and keyless versions
- Standard, full-range dimmer sockets
- Hi-lo dimmer, Electrolier size
- Interiors, caps and shells for metal shell lampholders

Candelabra Lampholders



- Phenolic with octagonal flange design and leads
 - Fixture bracket series
 - Single-leg hickey with bushings, inside extrusions
 - Double-leg hickey with inside or outside extrusions
 - Snap-in mounting
- Phenolic with screw terminals
- Porcelain with screw terminals and snap-on lining per UL Standard 1571
- Candelabra sockets with outer threaded bodies
- Bayonet-type with single and double contacts
- Intermediate lampholders

Phenolic Shell Lampholders



- Medium base externally threaded 2-piece (cap and shell) in turn-knob, push-thru, pull-chain and keyless versions
- Phenolic caps, shells and ring

Switches



Push

- Single-pole, ON-OFF plastic and metal pushbutton with leads
- Fluorescent lamp starter
- Single-pole momentary
- All-plastic switches for use in corrosive applications

Rotary

- Single-pole ON-OFF with non-removable plastic or metal knob
- L-rated and 2-circuit/4-position versions
- Hardware for rotary switches


Toggle

- Single-pole, single-throw for double-insulated applications
- T-rated and AC-rated plastic toggles
- Heavy-duty, single-pole, double-pole

Pull Chain

- Single-pole ON-OFF with leads
- Heavy duty with Quickwire terminals, in various 2-circuit/3-position, 2-circuit/4-position sequences

Convenience Outlets and Receptacles

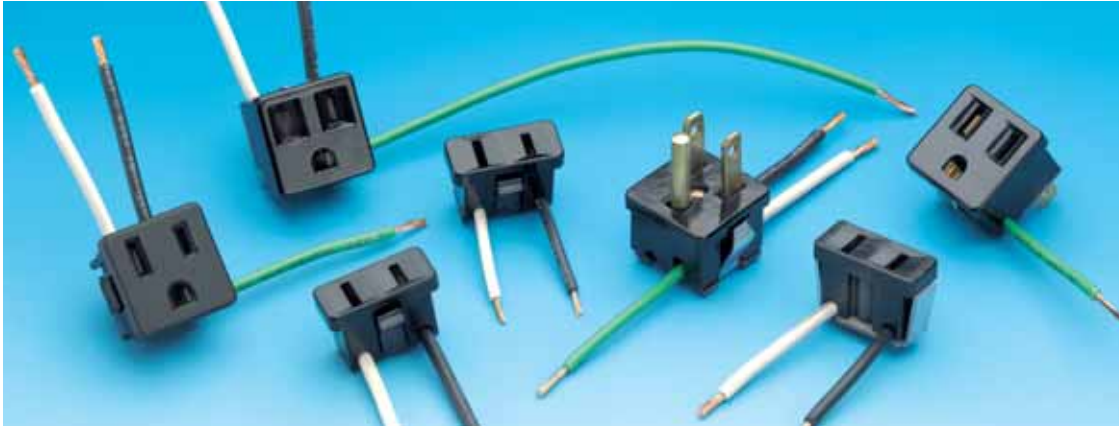

Outlets

- Choice of clips for different panel thicknesses
- Snap-in outlets with 2-pole, 3-wire grounding
- Wire leads or quick-connect terminals

Receptacles

- Straight blade receptacles, box mount
- DIN-rail mount receptacles

Personnel Protection Products



GFCI's (Ground Fault Circuit Interrupters)

- Right-angle GFCI plugs
- GFCI cord sets with automatic or manual reset
- GFCI extension cords, manual and automatic reset
- SmartLock® high current GFCI
- Panel-mount GFCI
- SmartLock® GFCI receptacles, hospital grade and feed-through
- LCDI cord sets for portable air conditioners

Surge Protective Devices



- Equipment cabinet devices
- Panel mount units for service entrance, sub-panel and individual branch circuit locations
- Hard-wired receptacles, industrial specification grade
- Rack-mount units for use on 19" equipment racks
- Low-voltage modules for factory automation and industrial control
- Secondary surge arrestors

Lighting Controls



- Architectural Specification dimmers and traditional lighting controls
- Wall-mount lighting controls
- Lamp dimmer/heater controls
- Table-top, lamp cord dimmers and dimmer sockets
- Multi-technology infrared and ultrasonic occupancy sensors
- Decora® infrared wall mount occupancy sensors

Fan and Motor Speed Controls



- Wall-mount fan speed controls
- Wall-mount motor and fan speed controls
- Motor speed controls
- AC combination devices for fan speed controls

Plugs and Connectors



- Python® and Commercial/Industrial straight blade plugs, connectors and angle plugs
- NEMA locking devices, including industrial, commercial and midget
- Wetguard® plugs, connectors and receptacles
- North American Watertight pin and sleeve and mechanical interlock devices
- ECT® cam-type and stage pin connectors

Leviton Manufacturing Co., Inc.

59-25 Little Neck Parkway, Little Neck, NY 11362-2591

Telephone: 1-800-833-3532 • FAX: 1-800-832-9538 • Email: info@leviton.com

Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

Visit Leviton's Website at www.leviton.com

© 2005 Leviton Manufacturing Co., Inc. All rights reserved.
C-700B/H5 tp

