


Hospital Grade Tamper-Resistant USB Charger Receptacle

Featuring a smart chip that recognizes and optimizes the flow of power to your device for fast and efficient charging

At a glance:

- Compatible with USB 2.0 devices
- 3.6A, 5V DC dual USB ports
- Balanced power USB ports
- Lowest vampire power

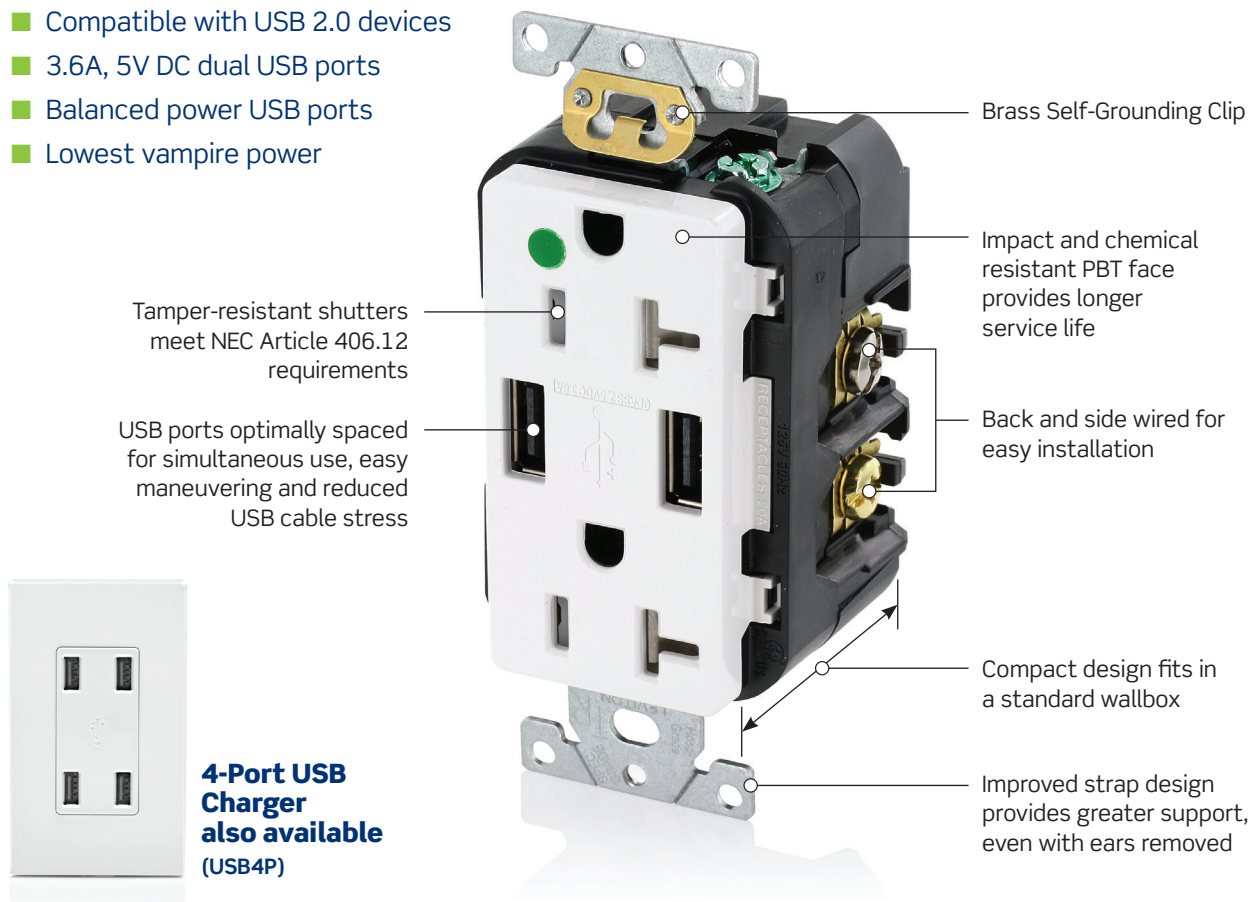

Ordering Information

Description		15A	20A
COLOR	Brown	T5632-HG	T5832-HG
	Ivory	T5632-HGI	T5832-HGI
	White	T5632-HGW	T5832-HGW
	Black	T5632-HGE	T5832-HGE
	Gray	T5632-HGG	T5832-HGG
	Lt. Almond	T5632-HGT	T5832-HGT
	Red	T5632-HGR	T5832-HGR


Common Applications

- Hospitals
- Urgent Care Centers
- Lobbies & Waiting Rooms
- Assisted Living Facilities
- Educational Institutions


Specifications

Description	T5632-HG	T5832-HG
AC Horsepower Rating		
At Rated Voltage	1/2HP	1HP
Electrical Specifications		
Amperage	15A	20A
Voltage	125V	125V
NEMA	5-15R	5-20R
Grounding	Self-Grounding	Self-Grounding
Pole	2	2
Wire	3	3
Dielectric Voltage	Withstands 2000V per CSA	Withstands 2000V per CSA
Temperature Rise	Max 30 °C after 100 cycles OL	Max 30 °C after 100 cycles OL
Environmental Specifications		
Flammability	Rated V0 per UL94	Rated V0 per UL94
Operating Temperature	-10 °C to 40 °C	-10 °C to 40 °C
Material Specifications		
Face Material	PBT	PBT
Body Material	PBT	PBT
Line Contacts	Brass	Brass
Terminal Clamp	Brass	Brass
Terminal Screws	Steel	Steel
Grounding Screws	Steel	Steel
Strap Material	Steel	Steel
Ground Clip	Brass	Brass
Mechanical Specifications		
Terminal ID	Brass-Hot, Green-Ground, Silver-Neutral	Brass-Hot, Green-Ground, Silver-Neutral
Terminal Accom.	14-12 AWG	14-12 AWG
Product ID.	Stamped on Strap	Stamped on Strap
Termination	Back and Side Wiring options	Back and Side Wiring options
Standards & Certifications		
NEMA	WD-1 and WD-6	WD-1 and WD-6
ANSI	C-73	C-73
Certification/Listing	CSA, NOM-ANCE	CSA, NOM-ANCE
Applicable Standards	UL 498 and 1310, CSA C22.2 Nos. 42 and 223	UL 498 and 1310, CSA C22.2 Nos. 42 and 223
Guarantees		
Product Warranty	5 Year Limited	5 Year Limited

Dimensions

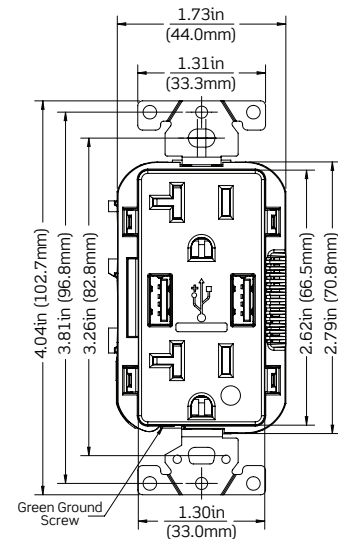

Front View

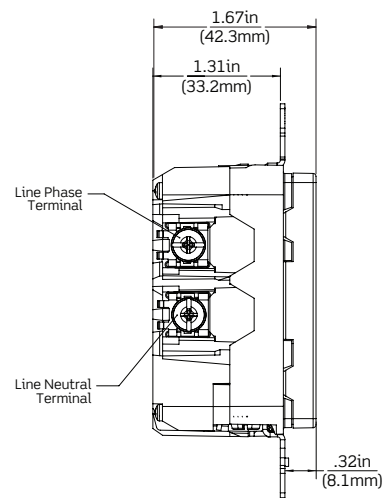

Side View

Visit our Website at:
www.leviton.com/industrial
 email: industrial@leviton.com

Q-873

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
 Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2014 Leviton Manufacturing Co., Inc. All rights reserved.

052014

